


## Catalog No. 1SAJ530000R1200

**Description:** UMC100.3 UC, Supply 110-240 V AC/DC, ATEX, 6 DI, 4 DO, PTC,

**UPC No** 4013614496943

**Home > Controls & Protective Relays > UMC**

UMC100.3 UC, Supply 110-240 V AC/DC, ATEX, 6 DI, 4 DO, PTC,

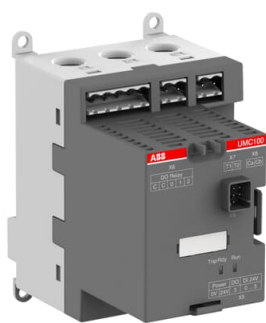

Representative Image

### Descriptors

Category	UMC
----------	-----

### Specifications

Product Name	Universal Motor Controller
Rated Control Supply Voltage	110 ... 240 V AC / DC
Ambient Air Temperature	Operation 0 ... +60 degree Celsius Storage -25 ... +70 degree Celsius
Resistance to Vibrations acc. to IEC 60068-2-6	4g, 2 ... 100 Hz
Resistance to Shock acc. to IEC 60068-2-27	15g / 1 shock / 11 ms
RoHS Status	Following EU Directive 2011/65/EU
Maximum Operating Voltage UL/CSA	Main Circuit 600 V AC Auxiliary Circuit 230 V AC / DC
Adjustable Rated Motor Current Ie	63 A
Analog Inputs	0

### Dimensions

Product Net Width	70 mm
Product Net Height	106 mm
Product Net Depth / Length	107 mm
Product Net Weight	315 gram

### Package Information

Package Level 1 Units	1 piece
Package Level 1 Width	142 mm
Package Level 1 Height	117 mm
Package Level 1 Depth / Length	122 mm
Package Level 1 Gross Weight	325 gram
Package Level 1 EAN	4013614496943

### Ordering

**by ABB**

## Ordering

ATEX Certificate	EC Type Examination certificate PTB ATEX UMC100.3
Minimum Order Quantity	1
Customs Tariff Number	85371091
ECCN	N
ECN	N
Analog Outputs	0