


Alternate Catalog No. LB6-CA
Catalog No. GJL1201903R0001
Description: LB6-CA Soldering Socket
UPC No 4013614051081
Home > Contactors & Starters > UL Listed IEC Contactors > AF Contactors

LB6-CA Soldering Receptacle 2-pole

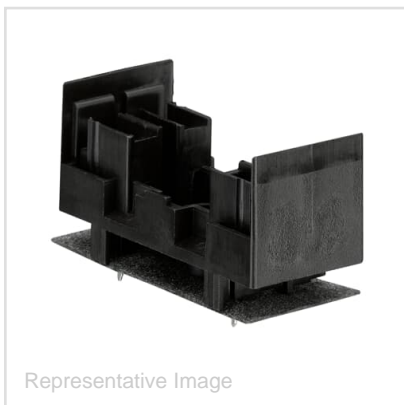

Representative Image

Descriptors

Category	AF Contactors
Block Contactor Type	Accessory

Specifications

Product Type	Mini Contactors (B6, B7)
Object Classification Code	X
Maximum Operating Voltage UL/CSA	Main Circuit 300 V AC Auxiliary Circuit 300 V AC
Reference Ambient Air Temperature	Operation-25 ... +50 °C Storage-25 ... +55 °C Storage-40 ... +80°C
Standards	UL 60947-1 UL 60947-4-1
Conventional Free-air Thermal Current	Auxiliary Circuit 8 A Main Circuit 8 A
Rated Insulation Voltage	690 V

Classifications

ETIM 4	EC002498 - Accessories for low-voltage switch technology
ETIM 6.0	EC002498 - Accessories for low-voltage switch technology
ETIM 7	EC002498 - Accessories for low-voltage switch technology
ETIM 5.0	EC002498 - Accessories for low-voltage switch technology
eClass	7.0 27379201

Dimensions

Product Net Weight	0.01kg
Product Net Depth / Length	22 mm
Product Net Width	44 mm
Product Net Height	20.3 mm

Package Information

Package Level 1 Width	115 mm
-----------------------	--------


by ABB

Package Information

Package Level 1 Depth / Length	280 mm
Package Level 1 Units	10 piece

Ordering

Minimum Order Quantity	1
------------------------	---